




SECURITY GRILLES

SG800

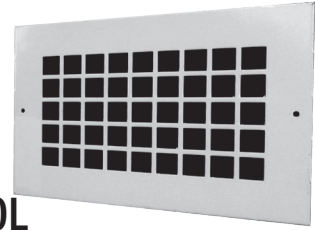

SG800L

STEEL

The SG800 series lattice and perforated face plates are designed for minimum security applications and offer an economical alternative for secure areas. They have the same dimensions as the Tuttle & Bailey T50, T60, T70 and T80 series grilles (duct plus 1-3/4" overall dimension) so the SG800 can be field assembled to the grille to provide a secured air passage. The heavy construction offers a reliable duct barrier and provides maximum free area.

Note: Security screws are provided by others.

FEATURES

- SG800L: lattice face plate, 12 gauge steel, 13/16" x 13/16" square holes spaced on 1" centers with 3/16" fret, 66% free area
- SG800P: perforated face plate, 12 gauge steel, 5/16" round holes on 7/16" staggered centers
- Steel construction
- Standard finish is white (WH)


ACCESSORIES

- Countersunk screw holes, 3/16" diameter
- Straight screw holes, 3/16" diameter
- Steel opposed blade damper (SDFO - face operated) is welded to 1" sleeve
- Steel plaster frame (45)

Note: Security screws are provided by others.

Available Sizes

Min	Max
6x4	30x30
Product available in 2" increments only.	

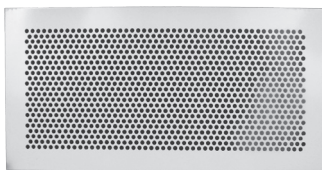

SG800P