

T70

GRILLES & REGISTERS

Tri-Flex Series, Steel Return

STEEL

T70 and T80 return grilles and registers have fixed bars spaced on 3/4" centers. Models T70D and T80D have face bars with 35° deflection. Models T70 and T80 have face bars with 0° deflection. The appearance matches the T50, T60 supply grilles and registers.

T75 and T85 return grilles and registers have fixed bars spaced on 1/2" centers. Models T75D and T85D have face bars with 35° deflection. Models T75 and T85 have face bars with 0° deflection. The appearance matches other Tri-Flex Series supply grilles and registers.

The streamlined bars and open spacing maintains an effective area capacity which minimizes intake velocity, reduces inlet pressure and provides quiet operation. Deflected blade grilles installed in a low or high sidewall location are vision proof with the grille bar deflection facing away from the line of sight.

FEATURES

- 1-1/4" nominal overlap margin
- Furnished with countersunk screw holes and mounting screws
- Steel construction with reinforced corners
- Available in 3/4" or 1/2" bar spacing
- Standard finish is White (WH)

ACCESSORIES


- Optional steel opposed blade damper (SOBD) is factory mounted and screwdriver operated from the face of grille
- Optional steel mounting frame (45) available for use in plaster applications to facilitate grille removal

Model Number Guide	
T70	3/4" spacing horizontal bars, 0° deflection
T70D	3/4" spacing horizontal bars, 35° deflection
T75	1/2" spacing horizontal bars, 0° deflection
T75D	1/2" spacing horizontal bars, 35° deflection
T80	3/4" spacing vertical bars, 0° deflection
T80D	3/4" spacing vertical bars, 35° deflection
T85	1/2" spacing vertical bars, 0° deflection
T85D	1/2" spacing vertical bars, 35° deflection

Available Sizes in One Piece	
Minimum	Maximum
6x4	48x48
Product available in one inch increments of width and height. Sizes greater than 48x48 are supplied in multiple sections.	



T70D

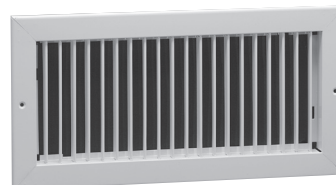

T80