




PRODUCT DIMENSIONS

SVPS

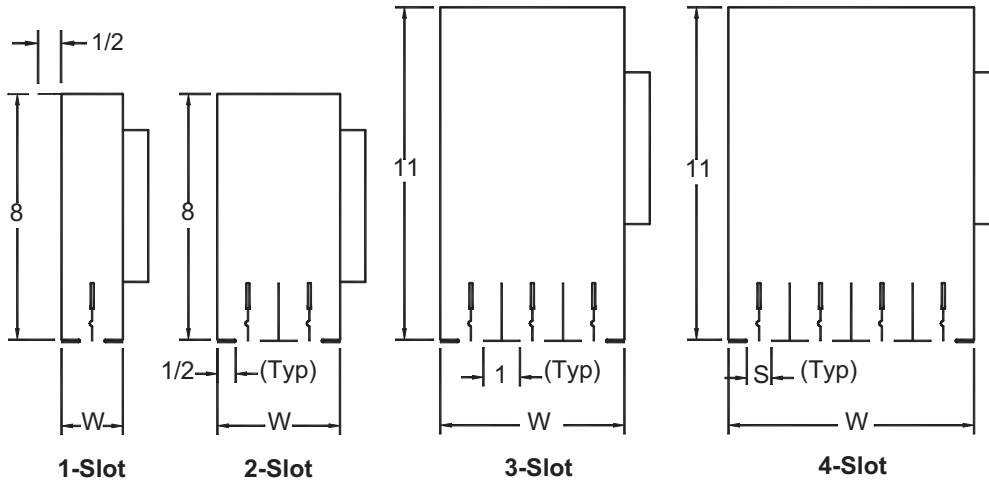


Available Inlet Sizes (in.)	Dimensions (in.)	
	A	B
5 Round	4-7/8	-
6 Oval	6-1/4	5-1/4
8 Oval	9-3/8	5-1/4
10 Oval	12-1/2	5-1/4
12 Oval	15-5/8	5-1/4

12" inlet size not available on 8" high plenums.

Optional center T-bars (1" wide) are shown above. Center channels are provided on 2, 3 and 4 slot models when T-bars are by others (LT0).

(S) (Slot Width)	(W) (Diffuser Width)			
	1-Slot	2-Slot	3-Slot	4-Slot
3/4	1-3/4	3-1/2	5-1/4	7
1	2	4	6	8
1-1/2	2-1/2	5	7-1/2	10


Plenum Slots

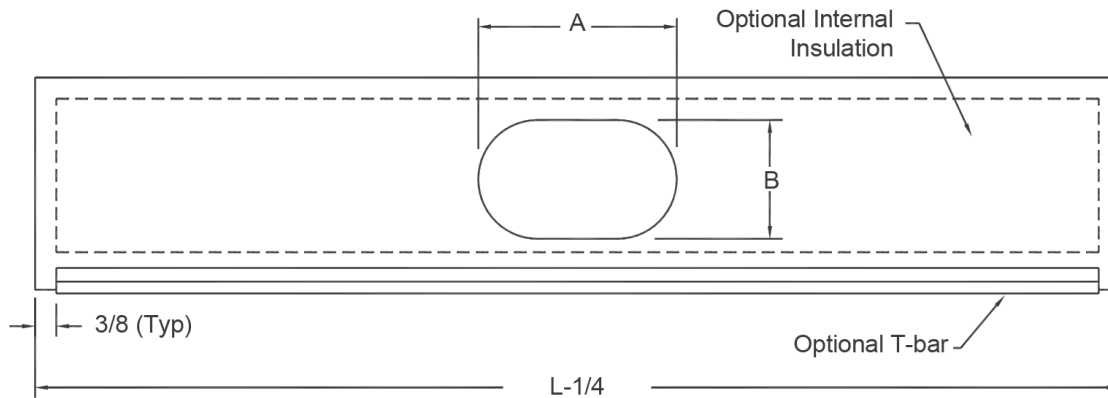

Available lengths (L): 24", 36", 48", 60"

PRODUCT DIMENSIONS

SVPS-NR


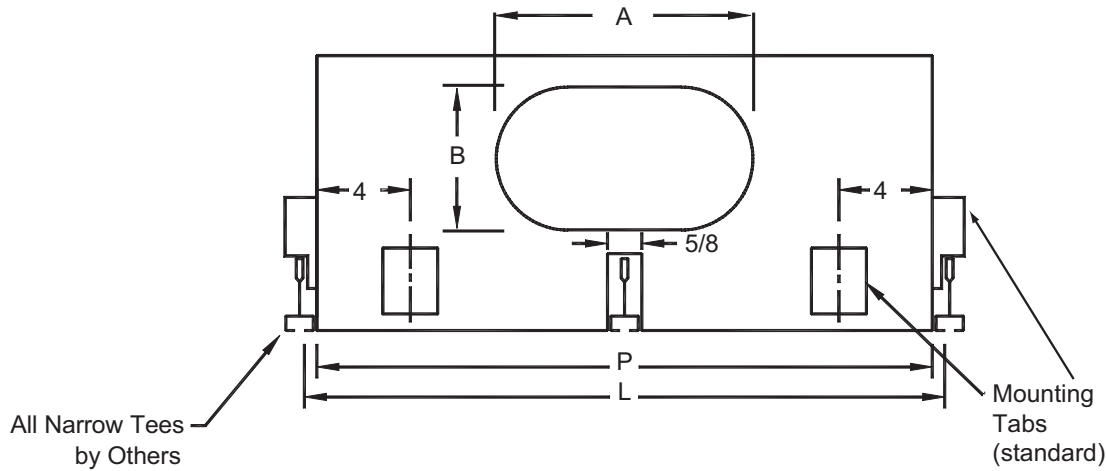


Available Inlet Sizes (in.)	Dimensions (in.)	
	A	B
5 Round	4-7/8	-
6 Oval	6-1/4	5-1/4
8 Oval	9-3/8	5-1/4
10 Oval	12-1/2	5-1/4
12 Oval	15-5/8	5-1/4

Nominal Length	Overall Length (L)	Plenum Length (P)
24	23-3/4	23-3/8
48	47-3/4	47-3/8

Narrow T-bar Detail

(All narrow tees provided by others)

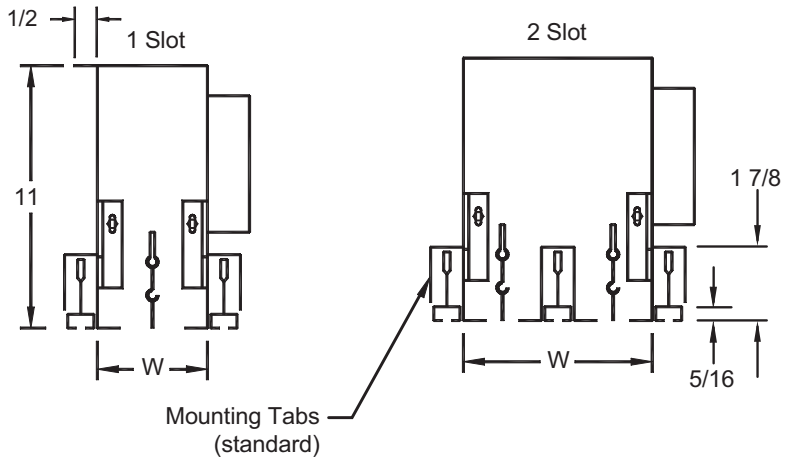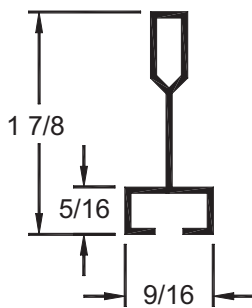

Accessories:

Earthquake tabs (not shown)
Standard is 2 tabs per diffuser

Slot Width	Diffuser Width	
	1-Slot	2-Slot
3/4	1-3/4	3-1/2
1	2	4
1-1/2	2-1/2	5

Notes:

1. Cross notch (CN) is provided on all 48" diffusers.
2. Center channel is provided on all 2 slot diffusers.