




- Matching return for PV, PP, and PM supply diffusers
- Hinged / removable face allows for easy access to damper
- Optional round damper is shipped loose and field mounted
- Model **PR** is all steel construction
- Model **APR** is steel backpan with aluminum face
- Standard finish is white

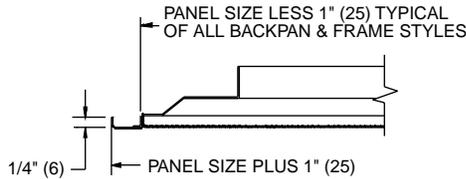


**Frame SF (Surface Mount)**  
\* minimum ceiling opening 23-1/4"

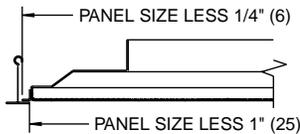

**Frame LT (Lay-in-T-Bar)**

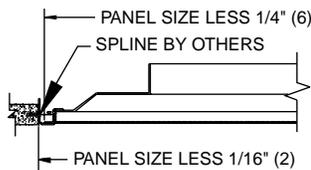


**Frame PL (Spline)**

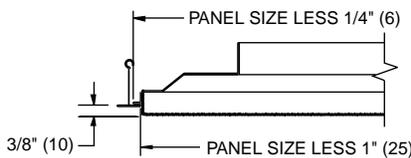


**Frame TG\*\* (Tegular)**

**\*\*NOTE:** Frame TG not available for Model APR


**Frame Detail:**  
24 x 24 Module Size

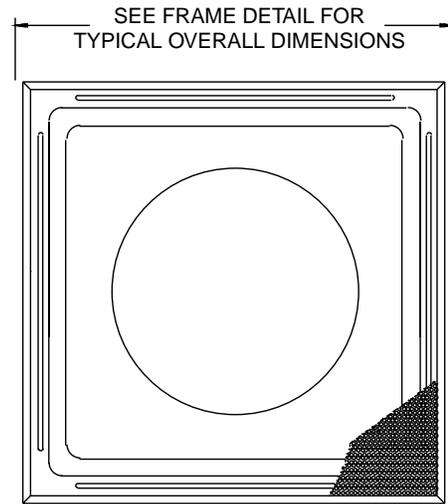


**PR**       **APR**

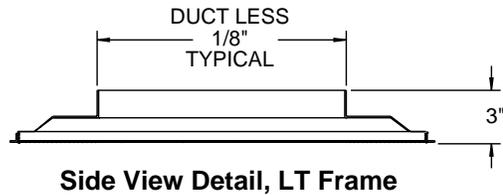

**Side View Detail, LT Frame**

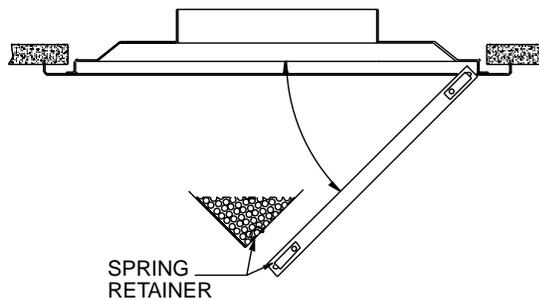

**Face Hinge Detail**

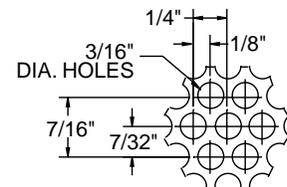

**Perforated Pattern Detail**  
(51% free area)

Dimensions are in inches. Product information subject to change without notice.

PROJECT:	SUBMITTED BY:	DATE: 7/02/01	SD - 1781
ARCHITECT:		<b>PR, APR Round Neck</b>	
ENGINEER:		Perforated Return	
CONTRACTOR:		24 x 24 Module Size	
LOCATION:			