

T125

GRILLES & REGISTERS

Heavy Duty Supply Tri-Flex

STEEL

T125 and T155 heavy duty supply grilles and registers are designed to take maximum abuse in areas requiring impact resistant applications such as gymnasiums, arenas, and industrial areas. The steel construction consists of a steel 18 gauge margin with 14 gauge blades.

The T125 is a single deflection supply with individually adjustable blades spaced on 1/2" centers.

The T155 is a double deflection supply with front blades spaced on 1/2" centers and rear blades spaced on 3/4" centers. Each blade on the T155 is individually adjustable.

FEATURES

- 1-1/4" nominal overlap margin
- Heavy duty steel construction (18 gauge frame, 14 gauge blades)
- Model T125: single deflection with blades spaced on 1/2" centers
- Model T155: double deflection with front blades spaced on 1/2" centers, rear blades spaced on 3/4" centers
- Individually adjustable blades hold deflection setting under typical conditions of pressure and velocity
- Support bars on 8" centers
- Standard finish is White (WH)


ACCESSORIES

- Optional steel opposed blade damper (SOBD) is factory mounted and screwdriver operated from the face of grille
- Optional steel mounting frame (45) available for use in plaster applications to facilitate grille removal

Available Sizes in One Piece

Minimum	Maximum
6x4	48x48

Product available in one inch increments of width and height. Sizes greater than 48x48 are supplied in multiple sections.

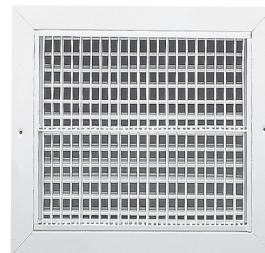

T155