



**M Series
LT Margin**

CEILING DIFFUSERS

Louvered Face-Square Neck M, MA, AM, AMA

STEEL

ALUMINUM

The M, AM diffuser line includes a multitude of air patterns, sizes, and mounting methods, resulting in a broad offering of products for exceptional versatility and flexibility. All M, AM diffusers feature superior construction and a streamlined flush face appearance, making the M, AM the ultimate in diffuser design and quality.

The M, AM diffusers are constructed of a heavy-duty margin and a one-piece removable center core, which features multiple deflecting louvers. The core snaps in place without the use of tools. A unique horizontal lip on the deflecting louver ensures a tight ceiling air pattern for excellent mixing. The M Series diffusers are offered in steel (M) or aluminum (AM) construction.

The M, AM diffusers are offered with 1-way, 2-way, 3-way or 4-way air patterns in a multitude of arrangements. The M, AM diffusers provide exceptional horizontal ceiling patterns effective for cooling applications or can be installed in a high-sidewall application utilizing the 3-way or 1-way pattern. The MA and AMA series diffusers can be adjusted for either a horizontal ceiling pattern (cooling) or a downward vertical pattern (heating or spot cooling) by simply adjusting the integral deflector blades. Adjustment can be done manually from the face such that no tools are required


FEATURES

- Removable snap-in cores provide easy access to the mounting margin and neck damper
- Removable snap-in center cores are interchangeable between same size margins
- Standard finish is white (WH)


ACCESSORIES

- Steel opposed blade dampers (SMOBD)
- Aluminum opposed blade dampers (AMOBD)
- Steel plaster frame (SMF)
- Aluminum plaster frame (ASMF)
- Square to round adapter (SRM)

Note: Trim frames and dampers are ordered separately and shipped loose for field installation.

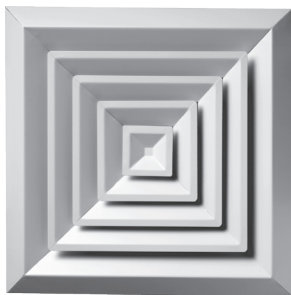

**M Series
SB Margin**

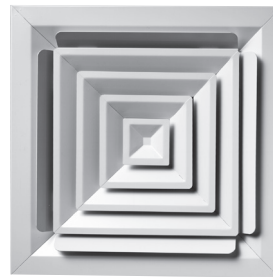

**MA Series
SF Margin**



MODEL NUMBER & SIZE GUIDE

M, MA, AM, AMA

Model Number Guide	
Model	Description
M	Steel, fixed pattern, square/rectangular neck
MA	Steel, adjustable pattern, square/rectangular neck
AM	Aluminum, fixed pattern, square/rectangular neck
AMA	Aluminum, adjustable pattern, square/rectangular neck

Margins: SF, SB

Available Sizes				
Neck Size	Model			
	M	MA	AM	AMA
MIN	6x6	6x6	6x6	6x6
MAX	48x48	24x24	48x48	24x24

Margins: LT, PL, YM

Available Sizes					
Module Size	Minimum Neck Size (All models)	Maximum Neck Size			
		M	MA	AM	AMA
12x12	6x6	9x9	6x6	9x9	6x6
24x24	6x6	21x21	18x18	21x21	18x18
48x24	12x12	45x21	21x18	45x21	18x18

Note: Neck sizes are available in 3" increments only