


- Model T70FB: horizontal bars, 0° fixed deflection
- Model T70DFB: horizontal bars, 35° fixed deflection
- Model T80FB: vertical bars, 0° fixed deflection
- Model T80DFB: vertical bars, 35° fixed deflection
- Face bars spaced on 3/4" centers
- Available in sizes from 6" x 4" to 48" x 36" in one inch increments (44" x 20" for LT)
- 1" filter frame standard; optional 2" available (filters furnished by others)
- Steel construction with hinges; no hinge option has removable face
- Standard finish is white

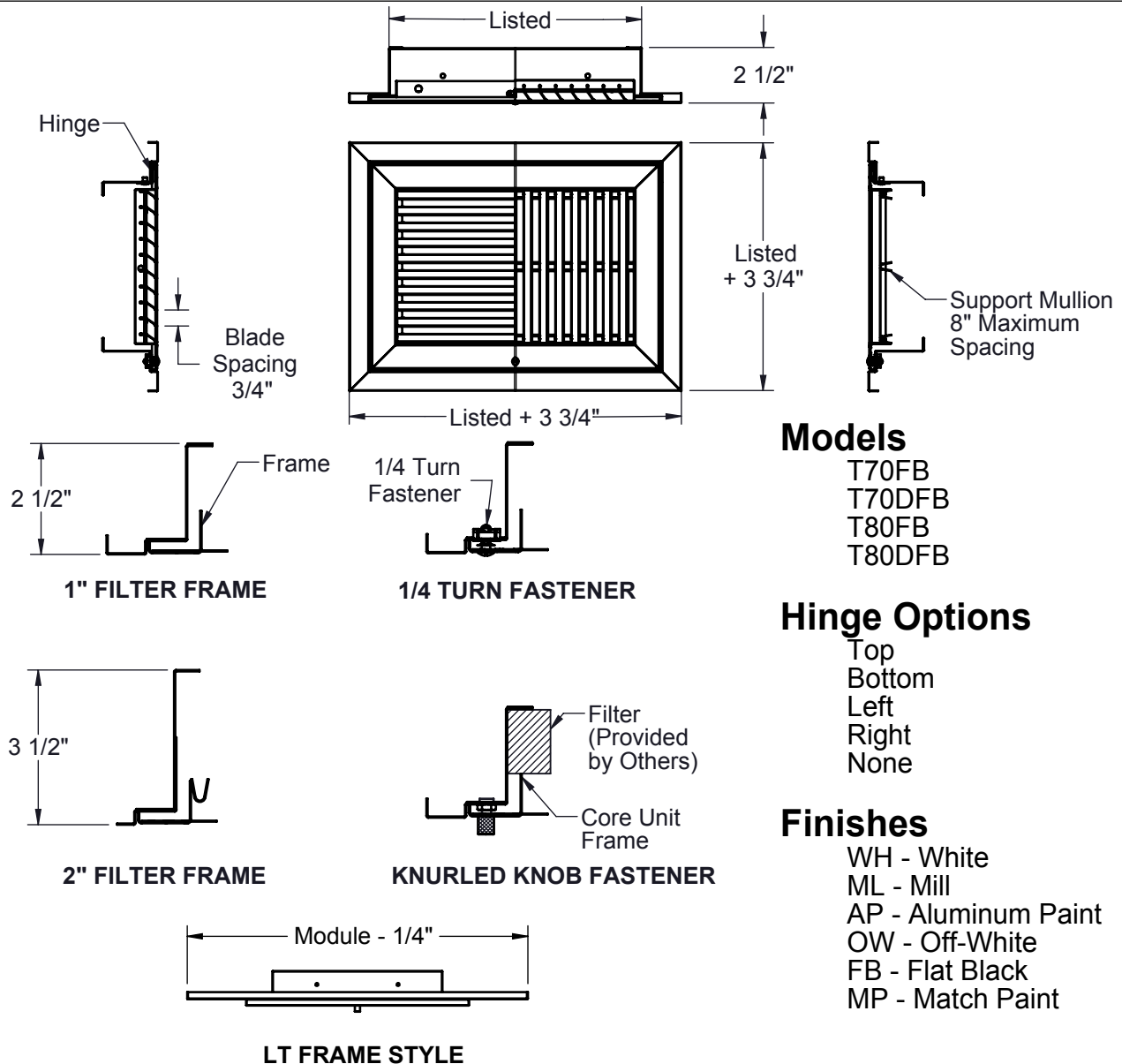

Models

T70FB
T70DFB
T80FB
T80DFB

Hinge Options

Top
Bottom
Left
Right
None

Finishes

WH - White
ML - Mill
AP - Aluminum Paint
OW - Off-White
FB - Flat Black
MP - Match Paint

Dimensions in inches

Job: _____	Tag: _____	T70FB/DFB & T80FB/DFB Return Grille with Filter Frame 3/4" Bar Spacing, Steel
Location: _____	Submitted By: _____	
Architect: _____		
Engineer: _____		
Contractor: _____	SD - 1766	Rev: E (10/17)

These drawings do not detail every aspect of the product. This submittal demonstrates general product dimensions; drawings are not to scale. Tuttle & Bailey reserves the right to make changes without notice. Copyright © 2017 Tuttle & Bailey www.tuttleandbailey.com