


- Steel (1300) or aluminum (A1300) construction
- ½" foil faced fiberglass insulation
- R value of 1.7
- Full face, 360° discharge
- Two earthquake tabs are standard
- Core is non-removable
- Removable plug in center cone allows damper adjustment
- Standard finish is white (WH)
- Optional round dampers (field installed)
- Optional Pattern Deflectors (PD) field installed for 1, 2 , or 3-way

Face View

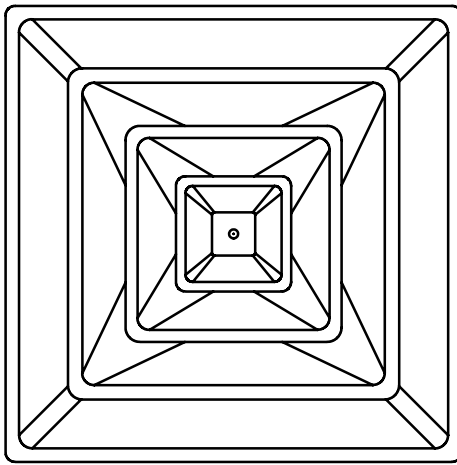

Options



Steel (1300)

Aluminum (A1300)

White (WH)
Mill (ML)
Alum. Paint (AP)
Off White (OW)
Flat Black (FB)
Match Paint (MP)

Neck Size	Ø A	B (1300)	B (A1300)
6	5 7/8	1	1 1/2
8	7 7/8	1	1 1/2
10	9 7/8	1 1/2	1 1/2
12	11 7/8	1 1/2	1 1/2
14	13 7/8	1 1/2	1 1/2
15	14 7/8	1 1/2	1 1/2

Frame Styles

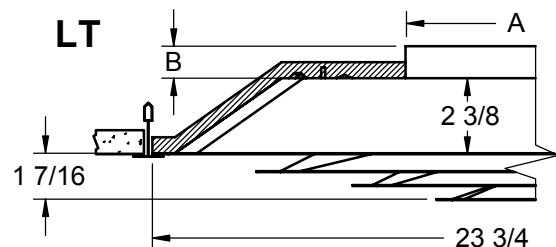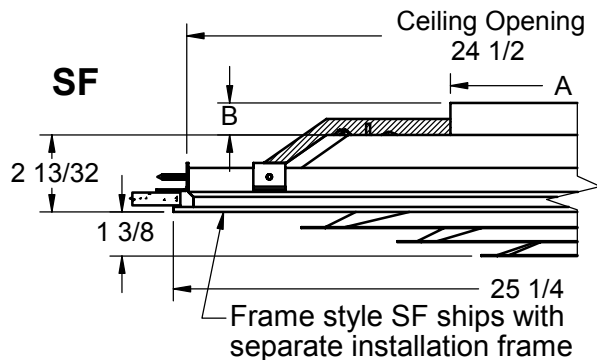

Dimensions in inches

Job: _____
Location: _____
Architect: _____
Engineer: _____
Contractor: _____

Submitted By: _____

SD-1905

Rev: A (07/04)

1300 & A1300 Series
Stepdown 3-Cone
Fixed Pattern Diffuser
Insulated Backpan
24x24 Module

These drawings do not detail every aspect of the product. This submittal demonstrates general product dimensions; drawings are not to scale. Tuttle & Bailey reserves the right to make changes without notice. Copyright © 2004 Tuttle & Bailey www.tuttleandbailey.com