

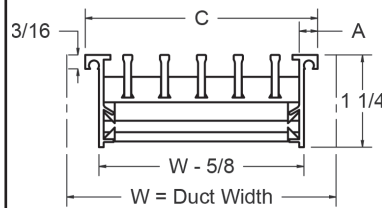
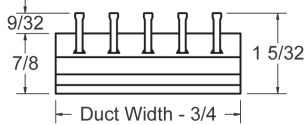
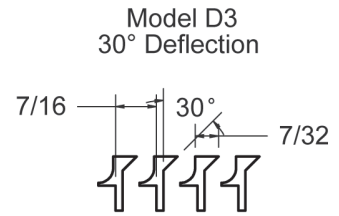
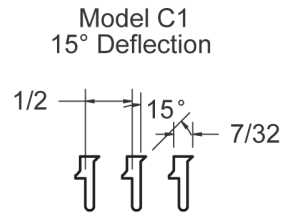
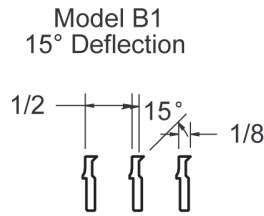
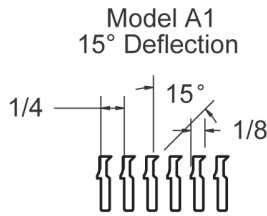
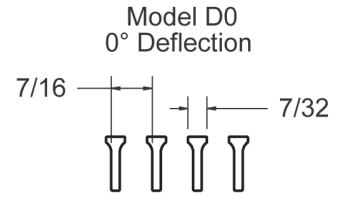
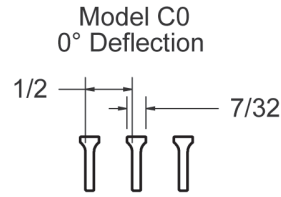


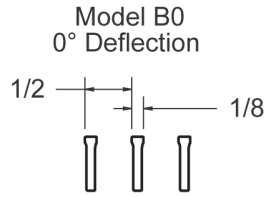



# ARCHITECTURAL STYLES

## 4000 Series

### Available Cores


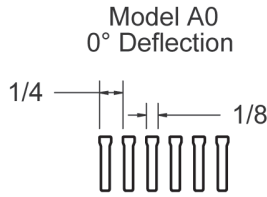


Margin Style	A	B	C
025	1/4	L - 1/4	W - 1/4
050	1/2	L + 1/4	W + 1/4
075	3/4	L + 3/4	W + 3/4
100	1	L + 1 1/4	W + 1 1/4
125	1 1/4	L + 1 3/4	W + 1 3/4

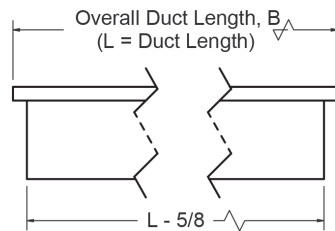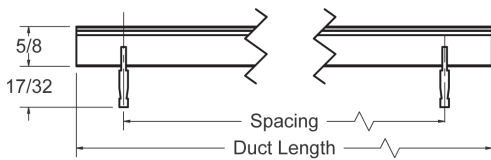

Core Only

Margins Only

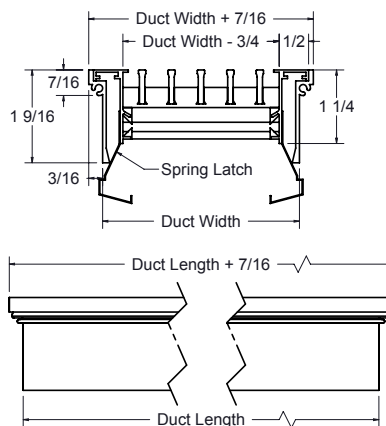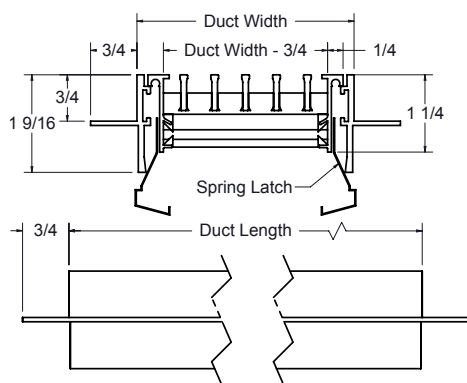

1SL

2SL

Linear/  
Slot Diffusers





# PRODUCT DIMENSIONS

## 4000 Series Fastening & Mounting

Type 0SH - Screw Holes  
(Not For Use with Margin 025)



Type 0SP - Spring Clip  
(Not for Use with Margin 025)



CMB - Concealed  
Mounting Brackets  
(Not Available on Core A0/A1)

