




- Double deflection with individually adjustable blades on 3/4" centers
- Model A54 has horizontal front blades / Model A64 has vertical front blades
- Aluminum construction
- Standard grille finish is white (WH)
- Damper option is mill finish only
- Available sizes are 6x4 to 48x48 in 1" increments (larger sizes in sections)

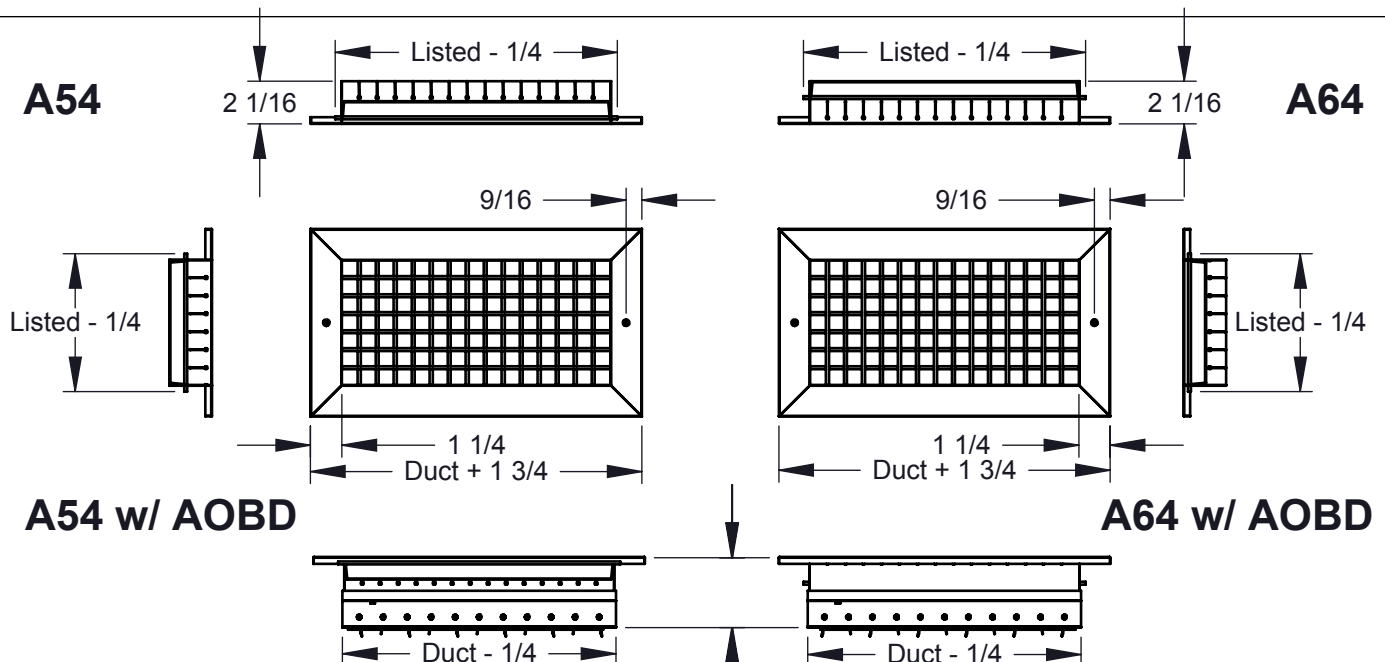

Concealed Mounting

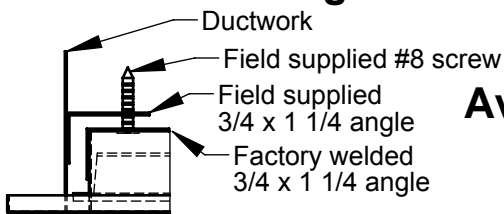

 LT Frame Style



Module	* Max Neck
12x12	9x9
24x12	21x9
24x24	21x21
48x24	45x21

Available Fastening Methods

- 01 - Screw Holes
- 02 - No Screw Holes
- 03 - Concealed

Available Colors

- White (WH) Mill (ML) Aluminum Paint (AP)
- Off-White (OW) Flat Black (FB)
- Match Paint (MP)

Accessories

- AOBD - Aluminum opposed blade damper
- SOBD - Steel opposed blade damper
- A45 - Aluminum mounting frame

* - When using a module for Lay-In T-Bar ceiling, this is the maximum neck size for specified module

Dimensions in inches

Job: _____	Tag: _____	A54 & A64 Supply Grille Aluminum Construction Double Deflection
Location: _____	Submitted By: _____	
Architect: _____		
Engineer: _____		
Contractor: _____	SD - 2001	Rev: E (08/17)