
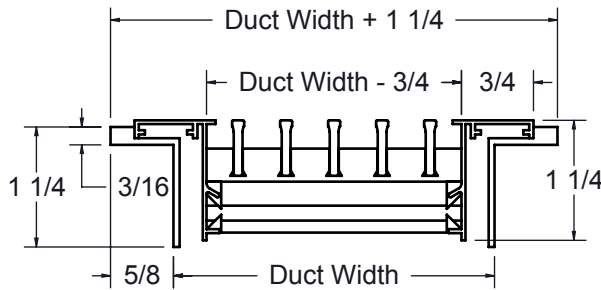


- Eight available core styles
- Extruded aluminum construction
- Size limitations are 6" x 2" minimum and 72" x 24" maximum for single piece
- Sizes available in 1/2" increments
- Core reinforcement option increases number of support bars to provide additional structural support
- Not recommended for sidewall or ceiling without concealed mounting bracket
- Standard finishes available are white (WH) and mill (ML)

## Accessories

### CMB - Concealed Mounting Brackets

(Not Available on Core A0/A1;  
max width available is 12")

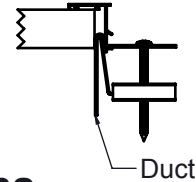


## Options









Standard  
Core Reinforced

## Finishes

WH - White  
ML - Mill  
AP - Aluminum Paint  
OW - Off-White  
FB - Flat Black  
MP - Match Paint  
CA - Clear Anodized

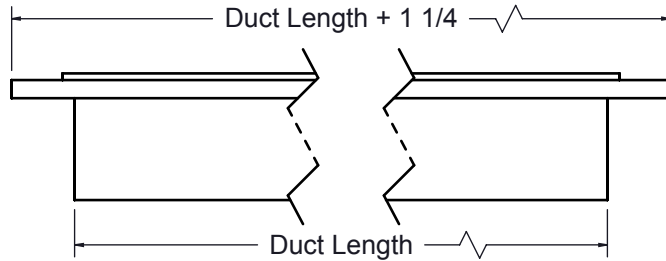

## Available Cores

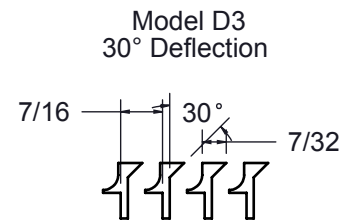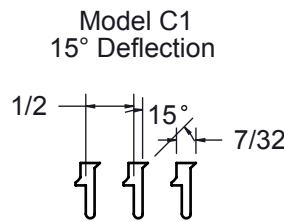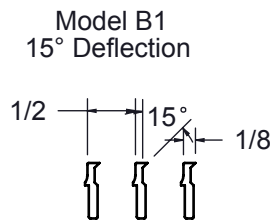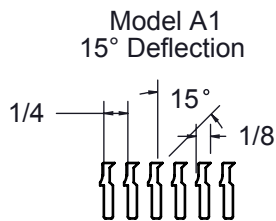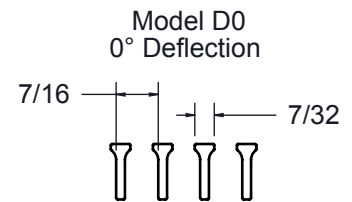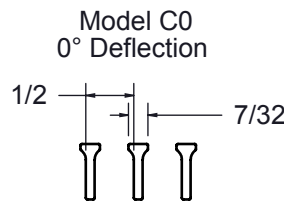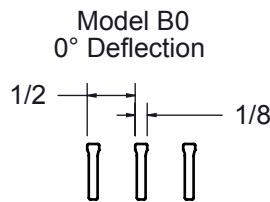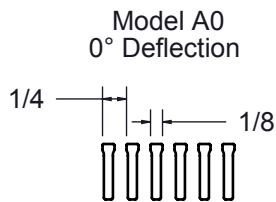

Dimensions in inches

Job: \_\_\_\_\_  
Location: \_\_\_\_\_  
Architect: \_\_\_\_\_  
Engineer: \_\_\_\_\_  
Contractor: \_\_\_\_\_

Tag: \_\_\_\_\_  
Submitted By: \_\_\_\_\_  
SD - 2077      Rev: D (02/11)

**4000 Linear Diffuser**  
**Mounting Style 400,**  
**3/4" Frame**  
**(Requires 075 Margin)**  
**Ceiling, Sidewall & Sill App.**