

A70

GRILLES & REGISTERS

Tri-Flex Return Grilles, Aluminum

ALUMINUM

A70 and A80 series return grilles and registers feature fixed bars spaced on 3/4" centers. Models A70 and A80 have face bars with 0° deflection. Model A70D and A80D have face bars with 35° deflection. The appearance matches the A50, A60 series supply grilles and registers.

A75 and A85 series return grilles and registers feature fixed bars spaced on 1/2" centers. Models A75 and A85 have face bars with 0° deflection. Model A75D, A85D has face bars with 35° deflection. The appearance matches the A50, A60 series supply grilles and registers.

The streamlined bars and open spacing maintains an effective area capacity which minimizes intake velocity, reduces inlet pressure and provides quiet operation. Deflected bar grilles installed in a low or high sidewall location are vision proof with the grille deflection facing away from the line of sight.

FEATURES

- 1-1/4" nominal overlap margin
- Furnished with countersunk screw holes and mounting screws
- Aluminum construction
- Standard finish is White (WH)

ACCESSORIES

- Optional aluminum opposed blade damper (AOBD or SOBD) is factory mounted and screwdriver operated from face of grille
- Optional aluminum mounting frame (A45) available for use in plaster applications


Model Number Guide	
A70	3/4" spacing horizontal bars, 0° deflection
A70D	3/4" spacing horizontal bars, 35° deflection
A75	1/2" spacing horizontal bars, 0° deflection
A75D	1/2" spacing horizontal bars, 35° deflection
A80	3/4" spacing vertical bars, 0° deflection
A85	1/2" spacing vertical bars, 0° deflection
A80D	3/4" spacing vertical bars, 35° deflection
A85D	1/2" spacing vertical bars, 35° deflection

Available Sizes in One Piece	
Minimum	Maximum
6x4	48x48

Product available in one inch increments of width and height. Sizes greater than maximum width or height are built in multiple sections.



A70D

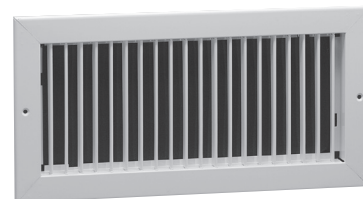

A80