



SPECIALTY PRODUCTS

Stainless Steel Supply Grilles T50SS, T60SS Series



T50SS

STAINLESS STEEL

The T50SS and T60SS series supply grilles and registers are constructed of stainless steel. They are an excellent choice for corrosive environments and critical room applications. They are available in single deflection (T50SS, T60SS) or double deflection (T54SS, T64SS). The blades are spaced on 3/4" centers and individually adjustable allowing maximum versatility in the field.

FEATURES

- Standard construction is #304 stainless steel (also available in #316 stainless steel)
- Single or double deflection
- Horizontal or vertical face blades
- Individually adjustable blades spaced on 3/4" centers
- Countersunk screw holes & stainless steel screws
- Standard finish is satin polish (SP)


ACCESSORIES

- Stainless steel opposed blade damper (SSOBD)

Available Sizes

Model	Min	Max
T50SS	4X4	48X48
T54SS	4X4	48X48

1" increments of width and height. Multiple sections furnished for sizes greater than maximum.

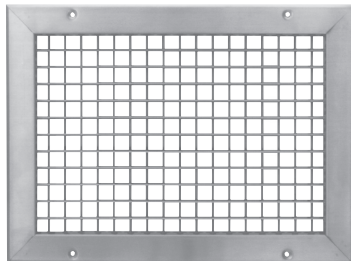

T54SS