



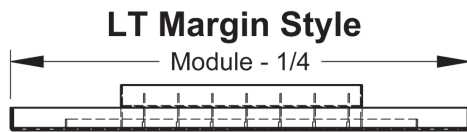


PRODUCT DIMENSIONS

T70, T70D, T75, T75D

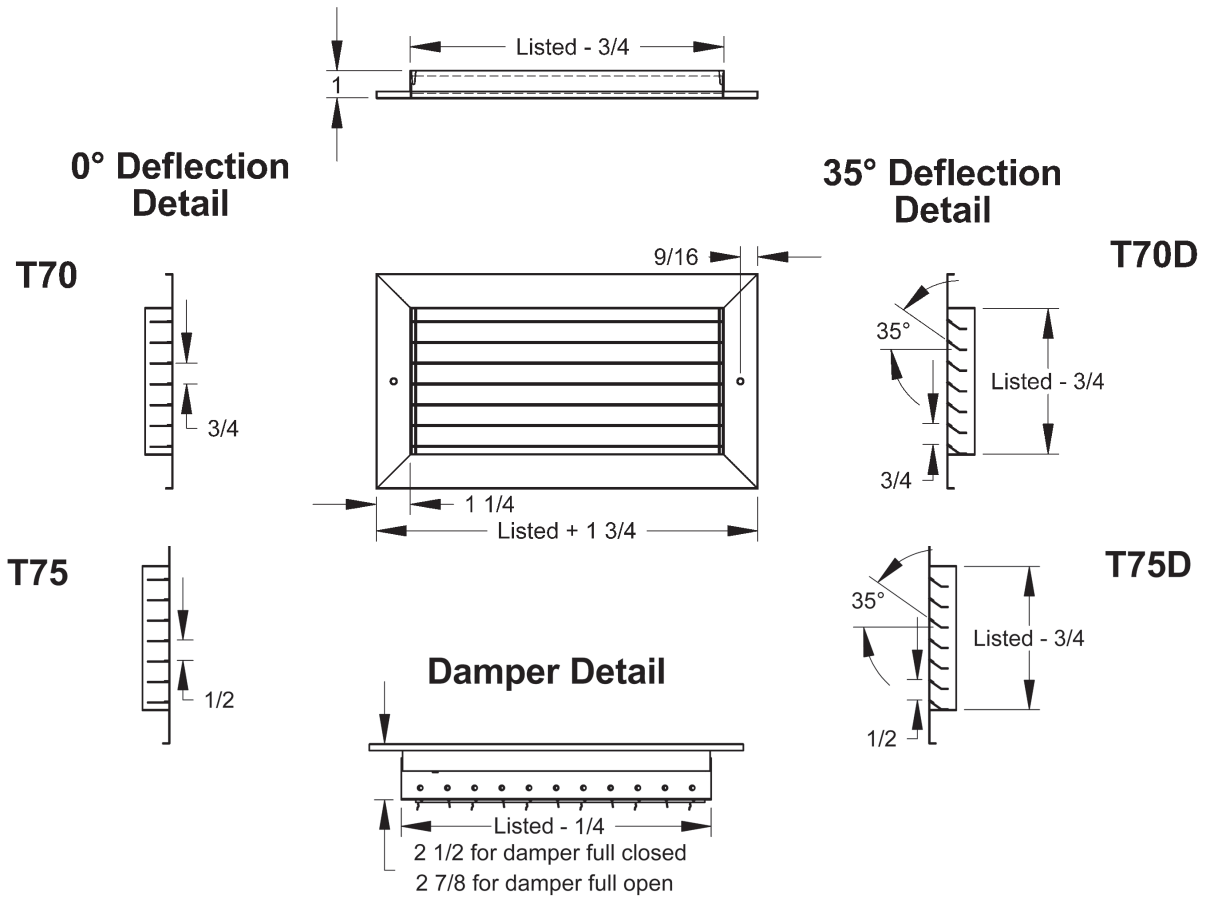

Module	*Max Neck
12x12	9x9
24x12	21x9
24x24	21x21
48x24	45x21

Concealed Mounting



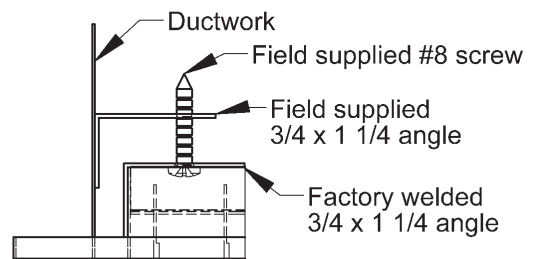


*When using a module for Lay-in T-Bar ceiling, this is the maximum neck size for specified module


PRODUCT DIMENSIONS

T80, T80D, T85, T85D

 
T80 (0° Deflection)

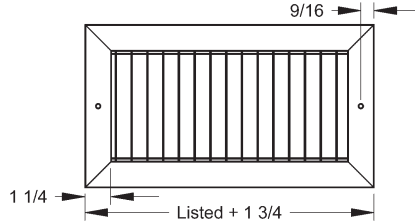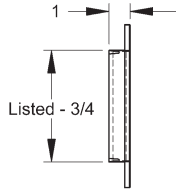




Damper Detail

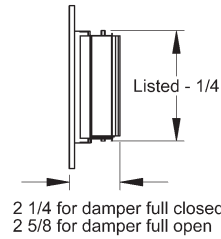


T80D (35° Deflection)

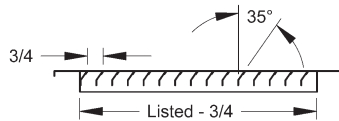


T85 (0° Deflection)

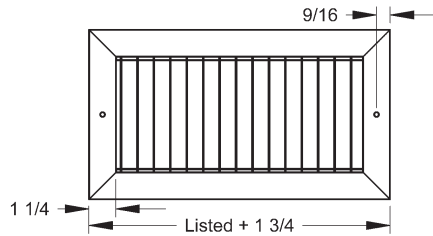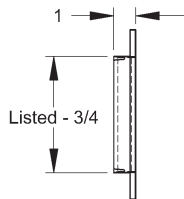 


Damper Detail

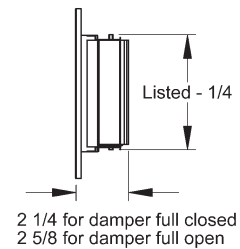

T85D (35° Deflection)

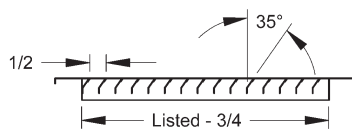


LT Margin Style

 

Module	*Max Neck
12x12	9x9
24x12	21x9
24x24	21x21
48x24	45x21

Concealed Mounting

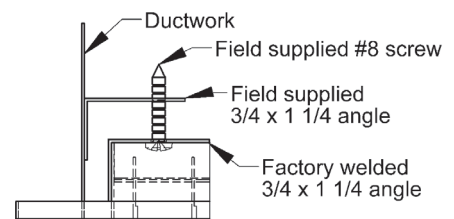

*When using a module for Lay-in T-Bar ceiling, this is the maximum neck size for specified module