

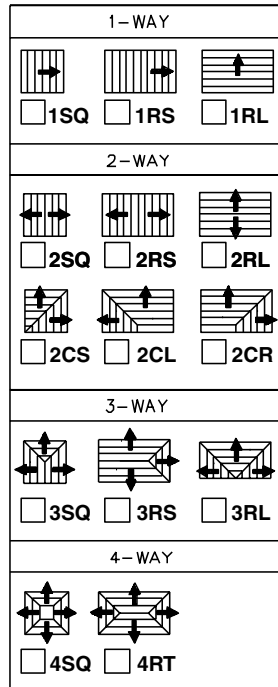
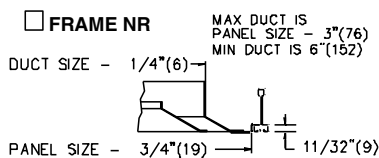
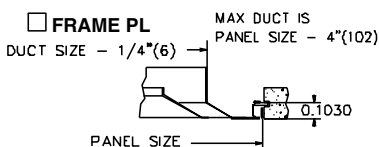
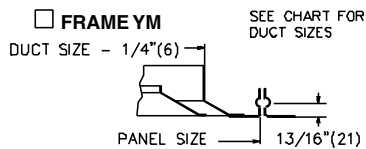
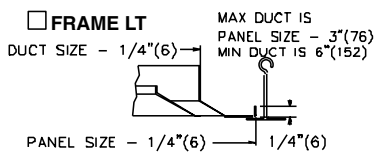
 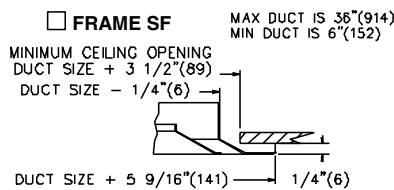
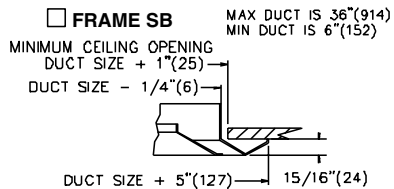



- Removable core
- Adjustable air pattern (horizontal or vertical)
- 1, 2, 3, or 4-way deflection pattern available (specify when ordering)
- Model **MA**: Steel construction, adjustable pattern
- Model **AMA**: Aluminum construction, adjustable pattern
- Neck sizes available in 3 increments only
- Optional opposed blade damper SMOBD (steel) & AMOBD (aluminum) are shipped loose and field installed
- Standard finish is white (WH)




SPECIFY DEFLECTION PATTERN WHEN ORDERING

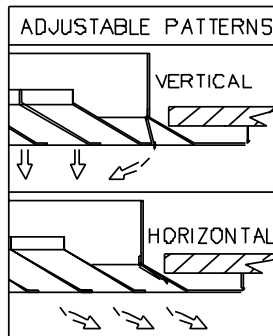

**MA/SMOBD**       **AMA/AMOBD**

 

**MA**       **AMA**

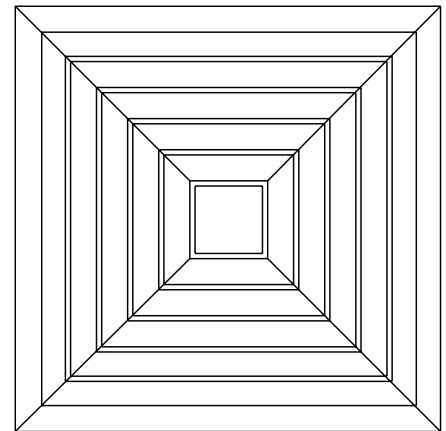

FACE VIEW

Frame SF  
4-way deflection pattern shown

Dimensions are in inches. Product information subject to change without notice.

Steel effective 12/18/00  
Aluminum effective 3/12/01

PROJECT: \_\_\_\_\_  
ARCHITECT: \_\_\_\_\_  
ENGINEER: \_\_\_\_\_  
CONTRACTOR: \_\_\_\_\_  
LOCATION: \_\_\_\_\_

SUBMITTED BY: \_\_\_\_\_

DATE: \_\_\_\_\_

SD - 1789

**M-Series**  
Adjustable Pattern  
Square/Rectangular Neck  
Steel and Aluminum